


GMCBU-UV110-120VAC Cut Sheet

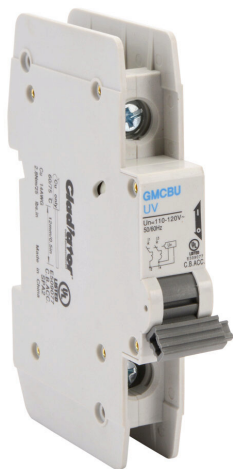

Gladiator undervoltage trip, left side mount, 110-120 VAC sensing range. For use with Gladiator GMCBU series miniature circuit breakers.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GMCBU-UV110-120VAC>

Technical Specifications

Brand	Gladiator
Item	Undervoltage trip
Mounting	Left side
Sensing Range	110-120 VAC
For Use With	Gladiator GMCBU series miniature circuit breakers

Agency Approvals

UL Listed File #	E509077
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/GMCBU-UV110-120VAC.pdf>
See store item page for other formats.