


GN-CSK141B Cut Sheet

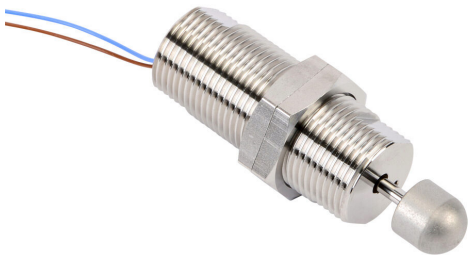

Metrol limit switch, vacuum, precision touch, 14mm diameter, threaded, 1mm pitch, 47mm length, 4mm radius head, stainless steel, 12mm plunger, 0.8N contact force, (1) N.C. contact(s), 1.6ft/0.5m cable length, pigtail.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GN-CSK141B>

Technical Specifications

Brand	Metrol
Item	Limit switch
Application	Vacuum
Switch Type	Precision touch
Diameter	14mm
Barrel Type	Threaded
Length	47mm
Head Type	4mm radius
Actuator Type	12mm plunger
Contact Force	0.8N
Contact Type	(1) N.C.

Cable Length	1.6ft/0.5m
Connection	Pigtail
Conductor Size	27 AWG
Stroke	5mm
Repeatability	0.01mm
Thread Pitch	1mm
Material	Stainless steel
Head Material	Stainless steel
IP Rating	IP40
Operating Temperature	0 to 120 deg C
Includes	Mounting hardware

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/GN-CSK141B.pdf>
See store item page for other formats.