


# GS30A-03TRA Cut Sheet

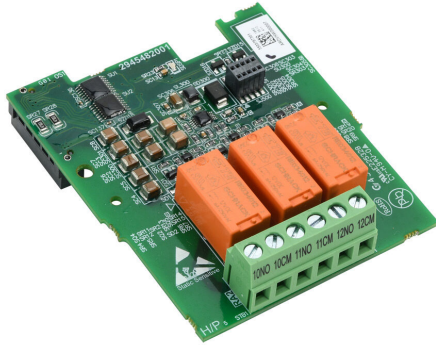

DURApulse GS30 series relay output module, 3-point, 250 VAC/30 VDC, (3) Form B (SPDT) relays, 2 isolated common(s), 1 point(s) per common. Screw terminal blocks included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GS30A-03TRA>

## Technical Specifications

<b>Brand</b>	DURApulse
<b>Item</b>	Output module
<b>I/O Module Type</b>	Relay
<b>Series</b>	GS30
<b>Number of Output Points</b>	3
<b>Nominal Output Voltage</b>	250 VAC/30 VDC
<b>Relay Configuration</b>	(3) Form B (SPDT) relays
<b>Number of Isolated Commons</b>	2

<b>Jumper Selectable Isolation</b>	No
<b>Number of Points per Common</b>	1
<b>Inductive Output Current</b>	2.4A
<b>Resistive Output Current</b>	6A
<b>Fuse Type</b>	User-supplied external fuse
<b>Includes</b>	Screw terminal blocks

## Agency Approvals

<b>UL Listed File #</b>	E176972
<b>UL Recognized File #</b>	E198015
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/GS30A-03TRA.pdf>  
See store item page for other formats.