


GS30A-06CDD Cut Sheet

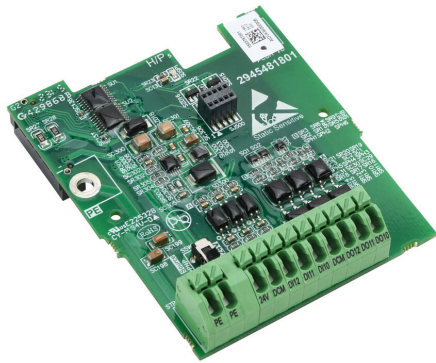

DURApulse GS30 series discrete combo module, Input: 3-point, 24 VDC, sinking/sourcing selectable, Output: 3-point, 48 VDC, sinking/sourcing selectable, 30mA/point, 50mA resistive output current. For use with GS30 series AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GS30A-06CDD>

Technical Specifications

| | |
|--|-----------------------------|
| Brand | DURApulse |
| Item | Combo module |
| I/O Module Type | Discrete |
| Series | GS30 |
| Number of Input Points | 3 |
| Nominal Input Voltage | 24 VDC |
| Discrete Input Type | Sinking/sourcing selectable |
| Number of Non-Isolated Discrete Input Commons | 1 |
| Number of Points per Discrete Input Common | 3 |
| Number of Output Points | 3 |

| | |
|---|-----------------------------|
| Nominal Output Voltage | 48 VDC |
| Discrete Output Type | Sinking/sourcing selectable |
| Number of Non-Isolated Discrete Output Commons | 1 |
| Number of Points per Discrete Output Common | 3 |
| Load Current | 30mA/point |
| Resistive Output Current | 50mA |
| Fuse Type | User-supplied external fuse |
| External Power Requirement | 24 VDC |
| For Use With | GS30 series AC drives |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E176972 |
| UL Recognized File # | E198015 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/GS30A-06CDD.pdf>
See store item page for other formats.