


# GS30A-06CDD Cut Sheet

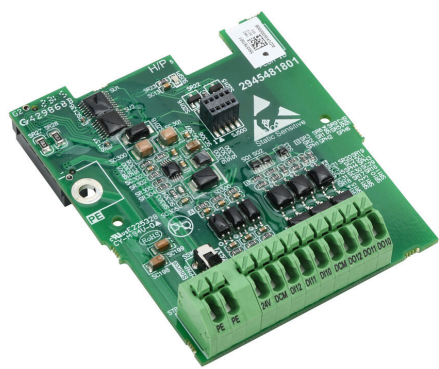

DURApulse GS30 series discrete combo module, Input: 3-point, 24 VDC, sinking/sourcing selectable, Output: 3-point, 48 VDC, sinking/sourcing selectable, 30 mA/point, 50 mA resistive output current. For use with GS30 series AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GS30A-06CDD>

## Technical Specifications

Brand	DURApulse
Item	Combo module
I/O Module Type	Discrete
Series	GS30
Number of Input Points	3
Nominal Input Voltage	24 VDC
Discrete Input Type	Sinking/sourcing selectable
Number of Non-Isolated Discrete Input Commons	1
Number of Points per Discrete Input Common	3
Number of Output Points	3

Nominal Output Voltage	48 VDC
Discrete Output Type	Sinking/sourcing selectable
Number of Non-Isolated Discrete Output Commons	1
Number of Points per Discrete Output Common	3
Load Current	30 mA/point
Resistive Output Current	50 mA
Fuse Type	User-supplied external fuse
External Power Requirement	24 VDC
For Use With	GS30 series AC drives

## Agency Approvals

UL Listed File #	E176972
UL Recognized File #	E198015
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/GS30A-06CDD.pdf>  
See store item page for other formats.