


GS30A-2AD2DA Cut Sheet

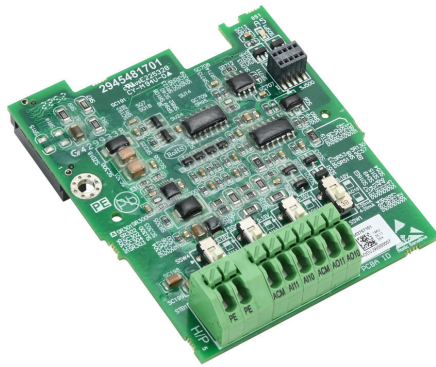

DURApulse GS30 series analog combo module, Input: 2-channel, current/voltage, 0-20 mA and 4-20 mA, 0-10 VDC, Output: 2-channel, current/voltage, 0-20 mA and 4-20 mA, 0-10 VDC.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GS30A-2AD2DA>

Technical Specifications

Brand	DURApulse
Item	Combo module
I/O Module Type	Analog
Series	GS30
Number of Input Channels	2
Input Signal Type(s)	Current/voltage
Analog Input Type	Sinking
Number of Non-Isolated Input Commons	1
Input Resolution	12-bit
Input Current Signal Range	0-20 mA and 4-20 mA
Input Voltage Signal Range	0-10 VDC
Number of Output Channels	2

Output Signal Type	Current/voltage
Analog Output Type	Sourcing
Number of Non-Isolated Output Commons	1
Output Resolution	12-bit
Output Current Signal Range	0-20 mA and 4-20 mA
Output Voltage Signal Range	0-10 VDC
External Power Requirement	24 VDC
For Use With	GS30 series AC drives
Includes	Spring clamp terminals

Agency Approvals

UL Listed File #	E176972
UL Recognized File #	E198015
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/GS30A-2AD2DA.pdf>
See store item page for other formats.