


# GS30A-CM-ECAT Cut Sheet

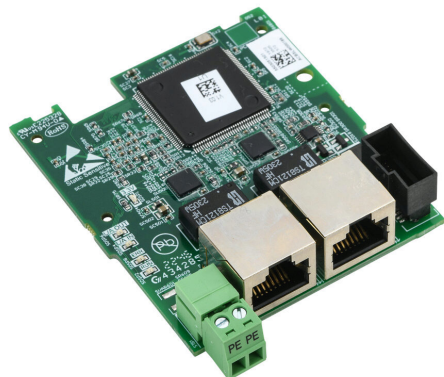

DURApulse GS30 series communication module, EtherCAT Slave, 2 ports, (2) Ethernet (RJ45) port(s). For use with GS30 series AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GS30A-CM-ECAT>

## Technical Specifications

|  |                       |
|--|-----------------------|
| <b>Brand</b>                                     | DURApulse             |
| <b>Item</b>                                      | Communication module  |
| <b>Series</b>                                    | GS30                  |
| <b>Number of Ports</b>                           | 2                     |
| <b>Buffered Ports</b>                            | No                    |
| <b>Communication Port and Connection Type(s)</b> | (2) Ethernet (RJ45)   |
| <b>Port Protocol(s)</b>                          | EtherCAT Slave        |
| <b>Port Speed(s)</b>                             | 100 Mbps auto-detect  |
| <b>For Use With</b>                              | GS30 series AC drives |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E176972                                |
| <b>UL Recognized File #</b> | E198015                                |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | None                                   |
| <b>RoHS Status</b>          | Yes (See CE Doc)                       |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/GS30A-CM-ECAT.pdf>  
See store item page for other formats.