


GSD3-24A-2CJ Cut Sheet

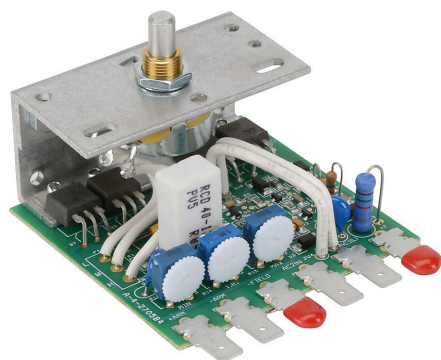

IronHorse GSD3 series DC general purpose drive, 12/24 VAC, 1-phase, 1/50 to 1/40hp at 12 VDC and 1/25 to 1/20hp at 24 VDC, 2A, open frame, J style mount, field-install reverse, potentiometer input, SCR output.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GSD3-24A-2CJ>

Technical Specifications

Brand	IronHorse
Item	Drive
Controller Type	General purpose
Series	GSD3
Voltage Type	DC
Number of Input Phases	1
Nominal Drive Input Voltage	12/24 VAC
Nominal Drive Output Voltage	Output up to 12/24 VDC
Horsepower by Voltage	1/50 to 1/40hp at 12 VDC and 1/25 to 1/20hp at 24 VDC
Amperage Rating	2A
Variable Torque Amperage Rating	0.15 - 2A
Control Mode	DC
Safe Torque Off (STO)	No

Temperature Rating	-10 to 45 deg C
Enclosure Type	Open frame
IP Rating	IP00
Mounting	J style
Input Signal	Potentiometer input
On/Off Switch	No
Shunt Field Supply	Yes
Output Type	SCR output
Reverse Capability	Field-install
Output Frequency Range	DC
Connector Type	1/4in quick-disconnect
SCCR Rating	SCCR exempt
For Use With	Permanent magnet DC, shunt wound DC and universal motors
Includes	Speed potentiometer with knob and 0-100% faceplate

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document