


# GVP-321C-12D Cut Sheet

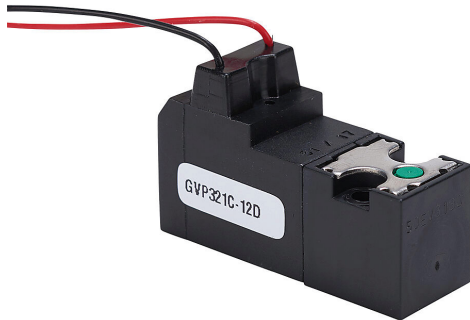

NITRA solenoid valve, 3-way, 2-position, N.C., single solenoid spring return, 15mm wide body, Cv=0.047, 12 VDC, 300mm 24AWG pigtail.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GVP-321C-12D>

## Technical Specifications

<b>Brand</b>	NITRA
<b>Series</b>	Miniature solenoid valves (GVP)
<b>Item</b>	Valve
<b>Working Fluid</b>	Air
<b>Valve Type</b>	Solenoid directional control
<b>Port Quantity</b>	3-way
<b>Number Of Positions</b>	2
<b>Valve Configuration</b>	N.C.
<b>Action</b>	Single solenoid spring return
<b>Body Material</b>	Glass-filled nylon
<b>Body Width</b>	15mm
<b>Mounting</b>	Optional manifold
<b>Stackable</b>	No
<b>Manual Override Type</b>	Momentary
<b>Flow Coefficient</b>	0.047
<b>Maximum Operating Pressure</b>	105 psi
<b>Minimum Operating Pressure</b>	0 psi
<b>Operating Voltage</b>	12 VDC
<b>Power Rating</b>	2.3W
<b>Electrical Connection</b>	300mm 24AWG pigtail
<b>Form Factor</b>	Miniature
<b>Includes</b>	Gasket and mounting hardware

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>