


H11131004-1 Cut Sheet

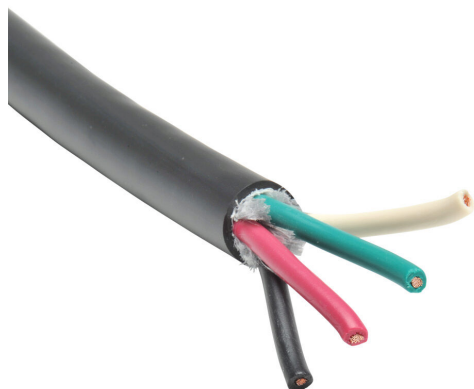

Helukabel portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 10 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H11131004-1>

Technical Specifications

| | |
|--------------------------------------|---------------------------------------|
| Brand | Helukabel |
| Item | Cord |
| Wire/Cable Type | Portable |
| UL Wire/Cable Type | SJOOW |
| Applicable Standards | UL 62, CSA Std. C22.2 No. 49 and MSHA |
| Application | General purpose |
| Flexibility | Flexible |
| Voltage Rating | 300V |
| Conductors | 4 conductors (includes ground) |
| Conductor Size | 10 AWG |
| Conductor Stranding | 105-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | EPDM thermoset rubber |

| | |
|---------------------------------------|--|
| Conductor Insulation Color | Black, white, red and green |
| Shielding | Unshielded |
| Jacket Material | CPE thermoset rubber |
| Jacket Color | Black |
| Nominal Overall Cable Diameter | 0.635in |
| Bulk Length | Cut to length |
| Package Type | <ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 95ft = 14 x 7in Reel• 96 to 140ft = 14 x 10in Reel• 141 to 210ft = 16 x 10in Reel• 211 to 295ft = 18 x 10in Reel• 296 to 385ft = 18 x 13in Reel• 386 to 860ft = 24 x 17in Wooden Reel• 861 to 1000ft = 30 x 17in Wooden Reel |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E192384 |
| UL Recognized File # | N/A |
| UL Hazardous File # | N/A |
| CE | View CE declarations |
| CSA File # | LL602586 |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |