


H11161005-1 Cut Sheet

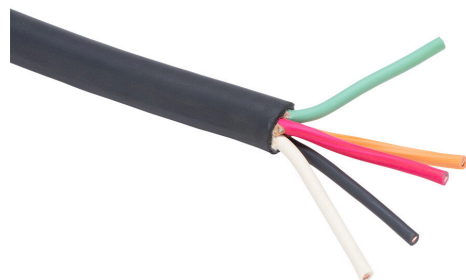

Helukabel portable cord, unshielded, SOOW, 600V, 5 conductors (includes ground), 10 AWG, EPDM thermoset rubber conductor insulation material, black, white, red, green and orange, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H11161005-1>

Technical Specifications

Brand	Helukabel
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Applicable Standards	UL 62, CSA Std. C22.2 No. 49 and MSHA
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	5 conductors (includes ground)
Conductor Size	10 AWG
Conductor Stranding	105-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red, green and orange

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.77in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 30ft = Coil• 31 to 65ft = 14 x 7in Reel• 66 to 95ft = 14 x 10in Reel• 96 to 145ft = 16 x 10in Reel• 146 to 200ft = 18 x 10in Reel• 201 to 260ft = 18 x 13in Reel• 261 to 585ft = 24 x 17in Wooden Reel• 586 to 935ft = 30 x 17in Wooden Reel• 936 to 1000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E192384
UL Recognized File #	N/A
UL Hazardous File #	N/A
CE	View CE declarations
CSA File #	LL602586
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document