


# H62026-1 Cut Sheet

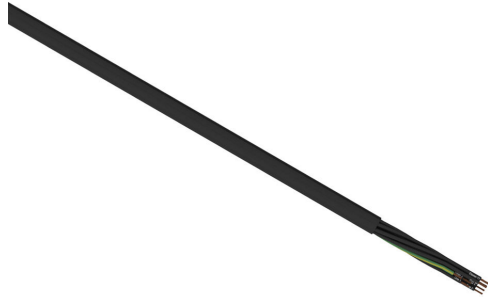

Helukabel TrayControl 600 flexible control cable, unshielded, 12 conductors (includes ground), 20 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62026-1>

## Technical Specifications

<b>Brand</b>	Helukabel
<b>Item</b>	Cable
<b>Series</b>	TrayControl 600
<b>Wire/Cable Type</b>	Control
<b>UL Wire/Cable Type</b>	ITC-ER, PLTC-ER and MTW
<b>Applicable Standards</b>	NFPA 79 and ECOLAB
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V (Types ITC-ER, PLTC-ER)
<b>Conductors</b>	12 conductors (includes ground)
<b>Conductor Size</b>	20 AWG
<b>Conductor Stranding</b>	10-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	PVC/Nylon

<b>Conductor Insulation Color</b>	Black with white numbers and green/yellow ground
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.437in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 205ft = 14 x 7in Reel</li><li>• 206 to 290ft = 14 x 10in Reel</li><li>• 291 to 445ft = 16 x 10in Reel</li><li>• 446 to 625ft = 18 x 10in Reel</li><li>• 626 to 815ft = 18 x 13in Reel</li><li>• 816 to 1000ft = 24 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E330431
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	257839
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>