


H62914-1 Cut Sheet

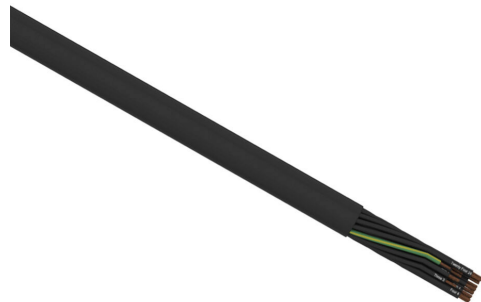

Helukabel TrayControl 600 flexible control cable, unshielded, 25 conductors (includes ground), 18 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62914-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	TrayControl 600
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER, WTTC, DP-1, ITC-ER, PLTC-ER and MTW
Applicable Standards	NFPA 79, UL 1277 and UL 2277
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, ITC-ER & PLTC-ER, MTW), 1000V (Type WTTC)
Conductors	25 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.685in
Bulk Length	Cut to length

Agency Approvals

UL Listed File #	E330430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257839
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document