


H62918-1 Cut Sheet

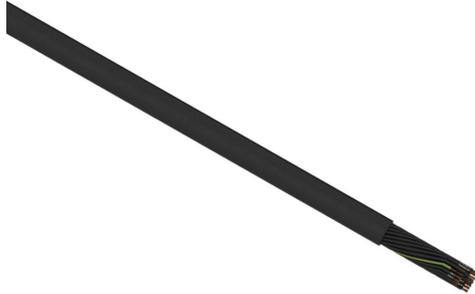

Helukabel TrayControl 600 flexible control cable, unshielded, 41 conductors (includes ground), 18 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62918-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	TrayControl 600
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER, WTTC, DP-1, ITC-ER, PLTC-ER and MTW
Applicable Standards	NFPA 79, UL 1277, UL 2277 and ECOLAB
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, ITC-ER & PLTC-ER, MTW), 1000V (Type WTTC)
Conductors	41 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.827in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 30ft = Coil• 31 to 55ft = 14 x 7in Reel• 56 to 80ft = 14 x 10in Reel• 81 to 125ft = 16 x 10in Reel• 126 to 175ft = 18 x 10in Reel• 176 to 225ft = 18 x 13in Reel• 226 to 510ft = 24 x 17in Wooden Reel• 511 to 810ft = 30 x 17in Wooden Reel• 811 to 1000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E330430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257839
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document