


H62930-1 Cut Sheet

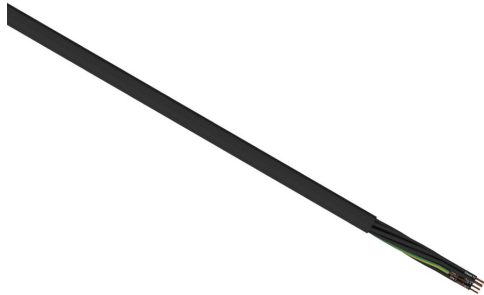

Helukabel TrayControl 600 flexible control cable, unshielded, 12 conductors (includes ground), 16 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62930-1>

Technical Specifications

| | |
|--------------------------------------|--|
| Brand | Helukabel |
| Item | Cable |
| Series | TrayControl 600 |
| Wire/Cable Type | Control |
| UL Wire/Cable Type | TC-ER, WTTC, DP-1, ITC-ER, PLTC-ER and MTW |
| Applicable Standards | NFPA 79, UL 1277, UL 2277 and ECOLAB |
| Application | General purpose |
| Flexibility | Flexible |
| Voltage Rating | 600V (Types TC, TC-ER, ITC-ER & PLTC-ER, MTW), 1000V (Type WTTC) |
| Conductors | 12 conductors (includes ground) |
| Conductor Size | 16 AWG |
| Conductor Stranding | 26-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | PVC/Nylon |

| | |
|---------------------------------------|---|
| Conductor Insulation Color | Black with white numbers and green/yellow ground |
| Shielding | Unshielded |
| Jacket Material | PVC |
| Jacket Color | Black |
| Nominal Overall Cable Diameter | 0.528in |
| Bulk Length | Cut to length |
| Package Type | <ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 140ft = 14 x 7in Reel• 141 to 200ft = 14 x 10in Reel• 201 to 305ft = 16 x 10in Reel• 306 to 430ft = 18 x 10in Reel• 431 to 555ft = 18 x 13in Reel• 556 to 1000ft = 24 x 17in Wooden Reel |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E330430 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | 257839 |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |