


H62934-1 Cut Sheet

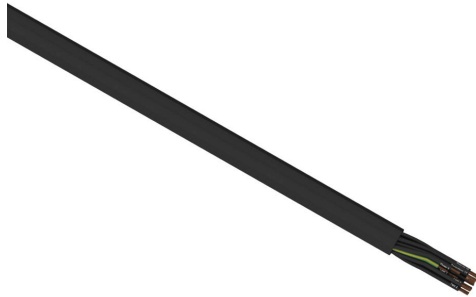

Helukabel TrayControl 600 flexible control cable, unshielded, 18 conductors (includes ground), 16 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62934-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	TrayControl 600
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER, WTTC, DP-1, ITC-ER, PLTC-ER and MTW
Applicable Standards	NFPA 79, UL 1277, UL 2277 and ECOLAB
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, ITC-ER & PLTC-ER, MTW), 1000V (Type WTTC)
Conductors	18 conductors (includes ground)
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.646in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 95ft = 14 x 7in Reel• 96 to 135ft = 14 x 10in Reel• 136 to 205ft = 16 x 10in Reel• 206 to 285ft = 18 x 10in Reel• 286 to 370ft = 18 x 13in Reel• 371 to 830ft = 24 x 17in Wooden Reel• 831 to 1000ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E330430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257839
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document