


# H62939-1 Cut Sheet

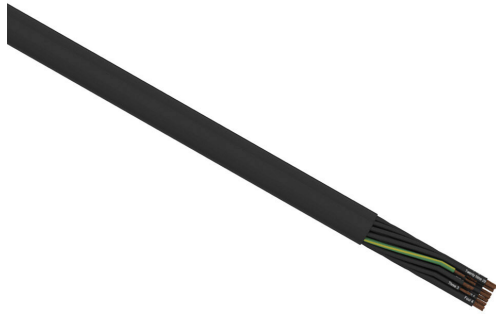

Helukabel TrayControl 600 flexible control cable, unshielded, 30 conductors (includes ground), 16 AWG, bare copper, PVC/ Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H62939-1>

## Technical Specifications

<b>Brand</b>	Helukabel
<b>Item</b>	Cable
<b>Series</b>	TrayControl 600
<b>Wire/Cable Type</b>	Control
<b>UL Wire/Cable Type</b>	TC-ER, WTTC, DP-1, ITC-ER, PLTC-ER and MTW
<b>Applicable Standards</b>	NFPA 79, UL 1277, UL 2277 and ECOLAB
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V (Types TC, TC-ER, ITC-ER & PLTC-ER, MTW), 1000V (Type WTTC)
<b>Conductors</b>	30 conductors (includes ground)
<b>Conductor Size</b>	16 AWG
<b>Conductor Stranding</b>	26-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	PVC/Nylon

<b>Conductor Insulation Color</b>	Black with white numbers and green/yellow ground
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.787in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 30ft = Coil</li><li>• 31 to 65ft = 14 x 7in Reel</li><li>• 66 to 90ft = 14 x 10in Reel</li><li>• 91 to 140ft = 16 x 10in Reel</li><li>• 141 to 195ft = 18 x 10in Reel</li><li>• 196 to 250ft = 18 x 13in Reel</li><li>• 251 to 560ft = 24 x 17in Wooden Reel</li><li>• 561 to 895ft = 30 x 17in Wooden Reel</li><li>• 896 to 1000ft = Large Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E330430
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	257839
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>