


H63142-1 Cut Sheet

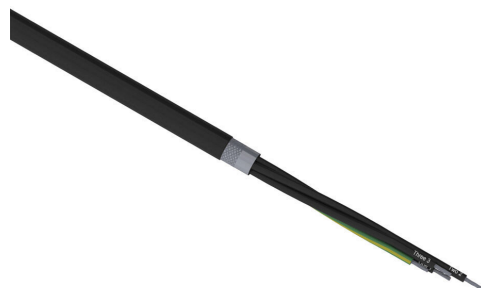

Helukabel TOPFLEX 600 VFD cable, shielded, 4 conductors (includes ground), 10 AWG, tinned copper, XLPE conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H63142-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	TOPFLEX 600
Wire/Cable Type	VFD
UL Wire/Cable Type	TC-ER and WTTC
Applicable Standards	UL 1277, UL 2277 and UL 44
Application	Drive and motor
Flexibility	Flexible
Voltage Rating	600V (Type TC), 1000V (Type WTTC, Flexible Motor Supply Cable)
Conductors	4 conductors (includes ground)
Conductor Size	10 AWG
Conductor Stranding	105-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Cross linked polyethylene (XLPE)

Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Overall foil and braid shielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.697in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 80ft = 14 x 7in Reel, 81 to 115ft = 14 x 10in Reel, 116 to 175ft = 16 x 10in Reel, 176 to 245ft = 18 x 10in Reel, 246 to 320ft = 18 x 13in Reel, 321 to 715ft = 24 x 17in Wooden Reel, 716 to 1145ft = 30 x 17in Wooden Reel, 1146 to 2500 = Large Wooden Reel

Agency Approvals

UL Listed File #	E330430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257839
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document