


H800067-1 Cut Sheet

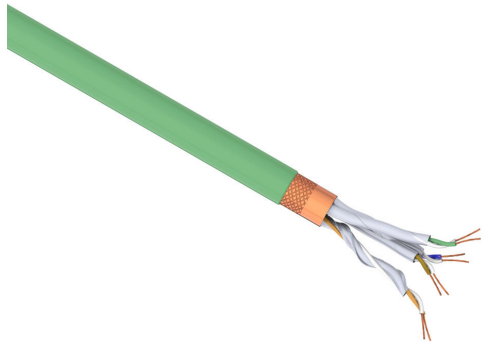

Helukabel HELUKAT continuous flexing Cat5 industrial Ethernet cable, individual and overall shielded, 4 twisted pairs, 26 AWG, 19-stranded, bare copper, polypropylene conductor insulation material, PUR jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H800067-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	HELUKAT
Protocol	Ethernet
Wire/Cable Type	Cat5 industrial Ethernet
UL Wire/Cable Type	AWM
Applicable Standards	Halogen free and UL 20236
Application	Data
Flexibility	Continuous flexing
Voltage Rating	30V
Conductors	4 twisted pairs
Conductor Size	26 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	Polypropylene

Conductor Insulation Color	Pair 1: blue, white, Pair 2: orange, white, Pair 3: green, white and Pair 4: brown, white
Shielding	Overall copperized polyester foil and tinned copper braid
Jacket Material	PUR
Jacket Color	Green
Nominal Overall Cable Diameter	0.295in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 450ft = 14 x 7in Reel• 451 to 640ft = 14 x 10in Reel• 641 to 980ft = 16 x 10in Reel• 981 to 1370ft = 18 x 10in Reel• 1371 to 1785ft = 18 x 13in Reel• 1786 to 2500ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E170315
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None