


H800068-1 Cut Sheet

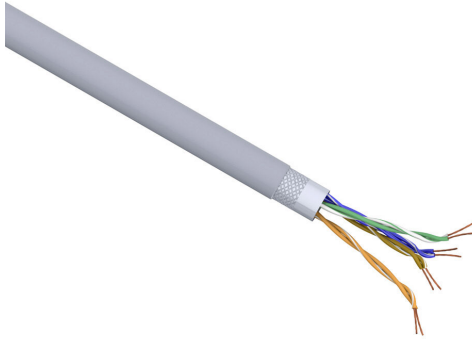

Helukabel HELUKAT flexible Cat5e industrial Ethernet cable, overall shielded, 4 twisted pairs, 26 AWG, 7-stranded, bare copper, polyolefin conductor insulation material, PUR jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H800068-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	HELUKAT
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	AWM
Applicable Standards	Halogen free, UL 758 and UL 21576
Application	Data
Flexibility	Flexible
Voltage Rating	1000V
Conductors	4 twisted pairs
Conductor Size	26 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	Polyolefin

Conductor Insulation Color	Pair 1: blue, white/blue, Pair 2: orange, white/orange, Pair 3: green, white/green and Pair 4: brown, white/brown
Shielding	Overall aluminized polyester foil and tinned copper braid
Jacket Material	PUR
Jacket Color	Gray
Nominal Overall Cable Diameter	0.228in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 750ft = 14 x 7in Reel• 751 to 1070ft = 14 x 10in Reel• 1071 to 1645ft = 16 x 10in Reel• 1646 to 2295ft = 18 x 10in Reel• 2296 to 2500ft = 18 x 13in Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E170315
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None