


H802185-1 Cut Sheet

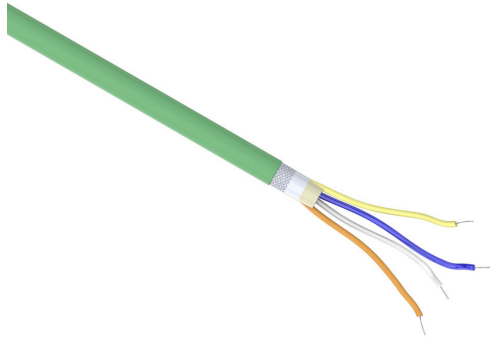

Helukabel HELUKAT flexible Profinet Type B cable, overall shielded, 1 star quad, 22 AWG, 7-stranded, tinned copper, FRNC conductor insulation material, FRNC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H802185-1>

Technical Specifications

Brand	Helukabel	Conductor Insulation Color	Pair 1: white, blue and Pair 2: yellow, orange
Item	Cable	Shielding	Overall aluminized polyester foil and tinned copper braid
Series	HELUKAT	Jacket Material	Flame-Retardent-Non-Corrosive (FRNC)
Protocol	Fieldbus and Cat5e Ethernet	Jacket Color	Green
Wire/Cable Type	Profinet Type B	Nominal Overall Cable Diameter	0.256in
UL Wire/Cable Type	CMG and PLTC	Bulk Length	Cut to length
Applicable Standards	Halogen free	Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 595ft = 14 x 7in Reel• 596 to 850ft = 14 x 10in Reel• 851 to 1305ft = 16 x 10in Reel• 1306 to 1820ft = 18 x 10in Reel• 1821 to 2370ft = 18 x 13in Reel• 2371 to 2500ft = 24 x 17in Wooden Reel
Application	Data		
Flexibility	Flexible		
Voltage Rating	60V		
Conductors	1 star quad		
Conductor Size	22 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	FRNC		

Agency Approvals

UL Listed File #	E312184
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None