


# H805704-1 Cut Sheet

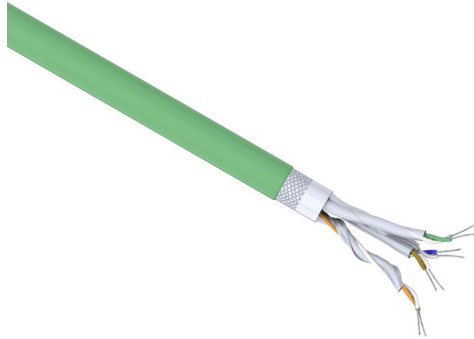

Helukabel HELUKAT flexible Cat6a industrial Ethernet cable, individual and overall shielded, 4 twisted pairs, 24 AWG, 7-stranded, tinned copper, foam polyethylene conductor insulation material, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H805704-1>

## Technical Specifications

<b>Brand</b>	Helukabel
<b>Item</b>	Cable
<b>Series</b>	HELUKAT
<b>Protocol</b>	Ethernet
<b>Wire/Cable Type</b>	Cat6a industrial Ethernet
<b>UL Wire/Cable Type</b>	CM
<b>Application</b>	Data
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	1000V
<b>Conductors</b>	4 twisted pairs
<b>Conductor Size</b>	24 AWG
<b>Conductor Stranding</b>	7-stranded
<b>Conductor Material</b>	Tinned copper
<b>Conductor Insulation Material</b>	Foam polyethylene

<b>Conductor Insulation Color</b>	Pair 1: blue, white, Pair 2: orange, white, Pair 3: green, white and Pair 4: brown, white
<b>Shielding</b>	Individual aluminum foil with overall aluminum foil and tinned copper braid
<b>Jacket Material</b>	PVC
<b>Jacket Color</b>	Green
<b>Nominal Overall Cable Diameter</b>	0.343in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 75ft = Coil</li><li>• 76 to 330ft = 14 x 7in Reel</li><li>• 331 to 475ft = 14 x 10in Reel</li><li>• 476 to 725ft = 16 x 10in Reel</li><li>• 726 to 1015ft = 18 x 10in Reel</li><li>• 1016 to 1320ft = 18 x 13in Reel</li><li>• 1321 to 2500ft = 24 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E312184
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	None