


H82838-1 Cut Sheet

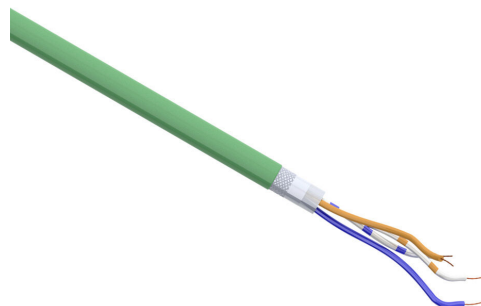

Helukabel HELUKAT continuous flexing Cat5e industrial Ethernet cable, overall shielded, 1 star quad, 26 AWG, 19-stranded, bare copper, polyolefin conductor insulation material, PUR jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/H82838-1>

Technical Specifications

Brand	Helukabel
Item	Cable
Series	HELUKAT
Protocol	Ethernet
Wire/Cable Type	Cat5e industrial Ethernet
UL Wire/Cable Type	AWM
Applicable Standards	Halogen free and UL 20963
Application	Data
Flexibility	Continuous flexing
Voltage Rating	30V
Conductors	1 star quad
Conductor Size	26 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper

Conductor Insulation Material	Polyolefin
Conductor Insulation Color	Pair 1: blue, white/blue and Pair 2: orange, white/orange
Shielding	Overall aluminum foil and tinned braid
Jacket Material	PUR
Jacket Color	Green
Nominal Overall Cable Diameter	0.189in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 1090ft = 14 x 7in Reel• 1091 to 1560ft = 14 x 10in Reel• 1561 to 2390ft = 16 x 10in Reel• 2391 to 2500ft = 18 x 10in Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E170315
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None