


# HBP14-25CBL2 Cut Sheet

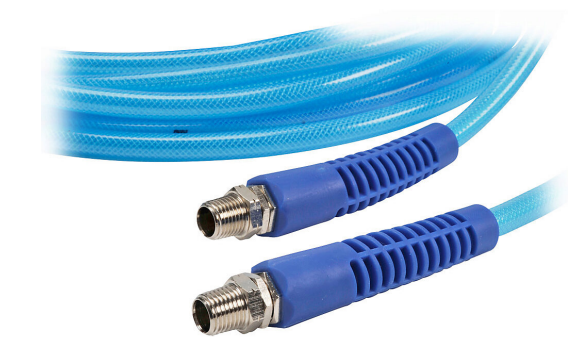

NITRA pneumatic hose, ether-based polyurethane, polyester reinforced, clear blue, 1/4in inside diameter, 0.375in outside diameter, 1/4in male NPT nickel-plated brass swivel fittings, 25ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBP14-25CBL2>

## Technical Specifications

Brand	NITRA
Item	Hose
Working Fluid	Air or inert gas
Material	Ether-based polyurethane
Reinforcement	Polyester
Color	Clear blue
Inside Diameter	1/4in
Outside Diameter	0.375in
Connection	1/4in male NPT nickel-plated brass swivel fittings
Working Length	25ft package
Operating Pressure	210 psi
Operating Temperature	-40 to +155 deg F

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/HBP14-25CBL2.pdf>  
See store item page for other formats.