


HBP38-50CBL2 Cut Sheet

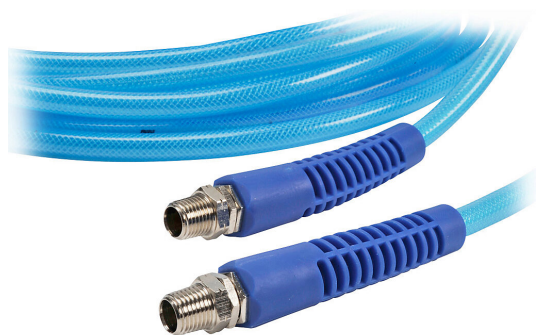

NITRA pneumatic hose, ether-based polyurethane, polyester reinforced, clear blue, 3/8in inside diameter, 0.5625in outside diameter, 1/4in male NPT nickel-plated brass swivel fittings, 50ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBP38-50CBL2>

Technical Specifications

Brand	NITRA
Item	Hose
Working Fluid	Air or inert gas
Material	Ether-based polyurethane
Reinforcement	Polyester
Color	Clear blue
Inside Diameter	3/8in
Outside Diameter	0.5625in
Connection	1/4in male NPT nickel-plated brass swivel fittings
Minimum Bend Radius	1.63in
Working Length	50ft package
Operating Pressure	210 psi
Operating Temperature	-40 to +155 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/HBP38-50CBL2.pdf>
See store item page for other formats.