


# HBP38-50CBL3 Cut Sheet

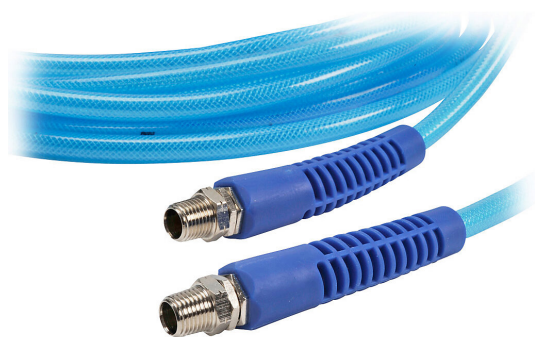

NITRA pneumatic hose, ether-based polyurethane, polyester reinforced, clear blue, 3/8in inside diameter, 0.5625in outside diameter, 3/8in male NPT nickel-plated brass swivel fittings, 50ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBP38-50CBL3>

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Hose
<b>Working Fluid</b>	Air or inert gas
<b>Material</b>	Ether-based polyurethane
<b>Reinforcement</b>	Polyester
<b>Color</b>	Clear blue
<b>Inside Diameter</b>	3/8in
<b>Outside Diameter</b>	0.5625in
<b>Connection</b>	3/8in male NPT nickel-plated brass swivel fittings
<b>Minimum Bend Radius</b>	1.63in
<b>Working Length</b>	50ft package
<b>Operating Pressure</b>	210 psi
<b>Operating Temperature</b>	-40 to +155 deg F

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/HBP38-50CBL3.pdf>  
See store item page for other formats.