


HBP38-50CBL3 Cut Sheet

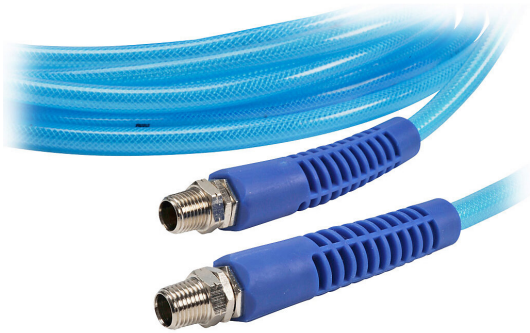

NITRA pneumatic hose, ether-based polyurethane, polyester reinforced, clear blue, 3/8in inside diameter, 0.5625in outside diameter, 3/8in male NPT nickel-plated brass swivel fittings, 50ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBP38-50CBL3>

Technical Specifications

| | |
|------------------------------|--|
| Brand | NITRA |
| Item | Pneumatic Hose |
| Material | Ether-based polyurethane |
| Reinforcement | Polyester |
| Color | Clear blue |
| Inside Diameter | 3/8in |
| Outside Diameter | 0.5625in |
| Connection | 3/8in male NPT nickel-plated brass swivel fittings |
| Working Length | 50ft package |
| Operating Pressure | 210 psi |
| Operating Temperature | -40 to +155 deg F |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |