


HBV1-100CBL Cut Sheet

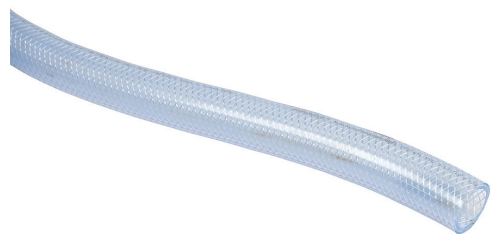

HydroMode potable water hose, polyester-reinforced PVC, clear blue, 1in inside diameter, 1.3in outside diameter, NSF/ANSI 61, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBV1-100CBL>

Technical Specifications

| | |
|------------------------------|--------------------------|
| Brand | HydroMode |
| Item | Potable water Hose |
| Material | Polyester-reinforced PVC |
| Color | Clear blue |
| Inside Diameter | 1in |
| Outside Diameter | 1.3in |
| Agency Approval | NSF/ANSI 61 |
| UV stabilized | No |
| Working Length | 100ft package |
| Operating Pressure | 125 psi |
| Operating Temperature | +15 to +150 deg F |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |