


HBV12-300CBL Cut Sheet

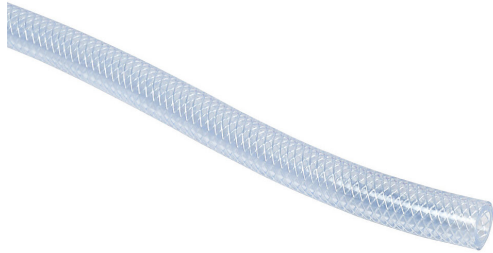

HydroMode potable water hose, polyester-reinforced PVC, clear blue, 1/2in inside diameter, 3/4in outside diameter, NSF/ANSI 61, 300ft reel.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBV12-300CBL>

Technical Specifications

Brand	HydroMode
Item	Potable water Hose
Material	Polyester-reinforced PVC
Color	Clear blue
Inside Diameter	1/2in
Outside Diameter	3/4in
Agency Approval	NSF/ANSI 61
UV stabilized	No
Working Length	300ft reel
Operating Pressure	200 psi
Operating Temperature	+15 to +150 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document