


# HBV34-300CBL Cut Sheet

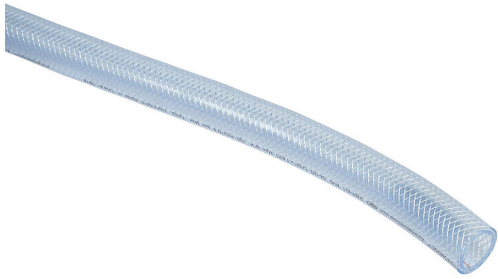

HydroMode potable water hose, polyester-reinforced PVC, clear blue, 3/4in inside diameter, 1.03in outside diameter, NSF/ANSI 61, 300ft reel.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBV34-300CBL>

## Technical Specifications

<b>Brand</b>	HydroMode
<b>Item</b>	Potable water Hose
<b>Material</b>	Polyester-reinforced PVC
<b>Color</b>	Clear blue
<b>Inside Diameter</b>	3/4in
<b>Outside Diameter</b>	1.03in
<b>Agency Approval</b>	NSF/ANSI 61
<b>UV stabilized</b>	No
<b>Working Length</b>	300ft reel
<b>Operating Pressure</b>	150 psi
<b>Operating Temperature</b>	+15 to +150 deg F

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>