


# HBV516-100CBL Cut Sheet

HydroMode potable water hose, polyester-reinforced PVC, clear blue, 5/16in (8mm) inside diameter, 0.531in outside diameter, NSF/ANSI 61, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HBV516-100CBL>

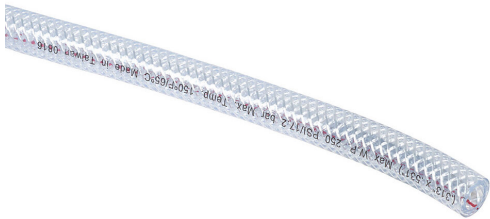

## Technical Specifications

Brand	HydroMode
Item	Potable water Hose
Material	Polyester-reinforced PVC
Color	Clear blue
Inside Diameter	5/16in (8mm)
Outside Diameter	0.531in
Agency Approval	NSF/ANSI 61
UV stabilized	No
Working Length	100ft package
Operating Pressure	250 psi
Operating Temperature	+15 to +150 deg F

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>