


HC38-12M-A Cut Sheet

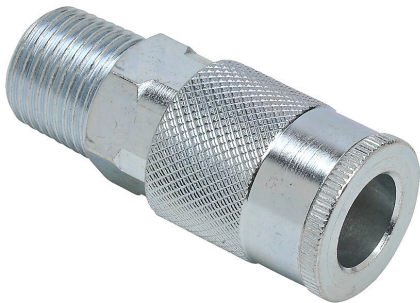

NITRA pneumatic quick disconnect fitting, coupling, steel body,
(1) 1/2in male NPT to (1) 3/8in industrial interchange.

For complete product information, please see this item on our
store at the following link:



<https://www.automationdirect.com/pn/HC38-12M-A>

Technical Specifications

Brand	NITRA
Item	Fitting
Working Fluid	Air or inert gas
Fitting Connection Type	Quick disconnect
Fitting Type	Coupling
Body Material	Steel
Fitting Measurement Type	SAE
Connection	(1) 1/2in male NPT and (1) 3/8in industrial interchange
Operating Pressure	150 psi
Operating Temperature	32 to 150 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document