


# HGR-37-060-A Cut Sheet

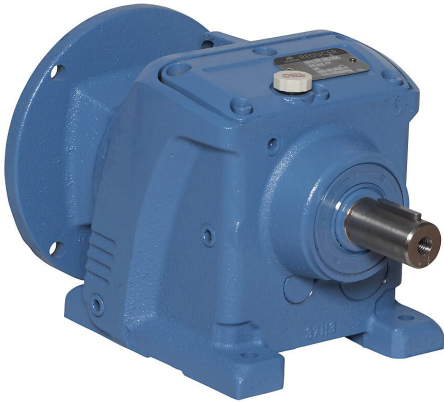

IronHorse heavy-duty helical gearbox, 60:1 ratio, 56C-Face input, inline, 1in diameter output shaft, nominal 0.82hp at 1.0 SF, 1770 lb-in mechanical output torque, Type-37 frame, cast iron housing, foot mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HGR-37-060-A>

## Technical Specifications

Brand	IronHorse
Item	Gearbox
Application	General purpose
Duty Rating	Heavy-duty
Gearbox Type	Helical
Gear Ratio	60:1
Speed Rating	1750rpm input / 29rpm output
Input Configuration	56C-Face
Input Power Rating	Nominal 0.82hp at 1.0 SF
Output Configuration	Inline
Gearbox Output Shaft Diameter	1in
Mechanical Output Torque	1770 lb-in
Thermal Output Torque	1770 lb-in
Frame	Type-37
Housing Material	Cast iron
Mounting	Foot
Includes	Motor mounting hardware
Finish	Anti-corrosion primer and paint
Lubrication Type	Pre-filled with HD320 mineral oil
Oil Seal Type	Double-lip

## Agency Approvals

RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>