


HM-1G Cut Sheet

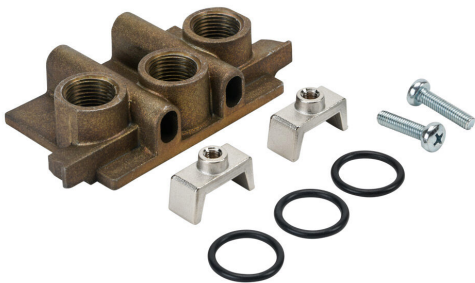

NITRA air manifold inlet, aluminum alloy, 145 psi (10 bar) maximum operating pressure, G3/8 female BSPP inlet(s), G3/8 female BSPP exhaust(s). For use with ISO 5599/1 size 1 manifolds.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HM-1G>

Technical Specifications

Brand	NITRA
Item	Manifold inlet
Working Fluid	Air
Material	Aluminum alloy
Maximum Operating Pressure	145 psi (10 bar)
Inlet Port	G3/8 female BSPP
Exhaust Port	G3/8 female BSPP
For Use With	ISO 5599/1 size 1 manifolds
Includes	Assembly clamps and seals

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/HM-1G.pdf>
See store item page for other formats.