


# HM-2BG Cut Sheet

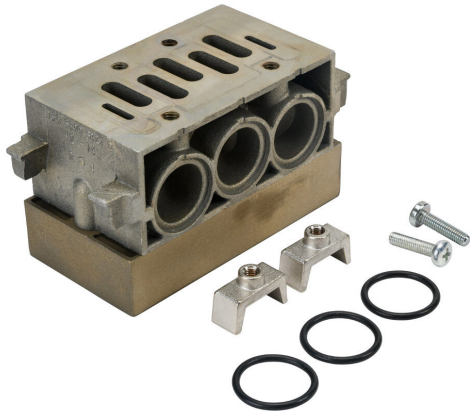

NITRA air manifold base, aluminum alloy, 145 psi (10 bar) maximum operating pressure, G3/8 female BSPP outlet(s), bottom orientation. For use with ISO 5599/1 size 2 solenoid valves.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HM-2BG>

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Air Manifold base
<b>Material</b>	Aluminum alloy
<b>Maximum Operating Pressure</b>	145 psi (10 bar)
<b>Outlet Port</b>	G3/8 female BSPP
<b>Hole Orientation</b>	Bottom
<b>For Use With</b>	ISO 5599/1 size 2 solenoid valves
<b>Includes</b>	Assembly clamps and seals

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/HM-2BG.pdf>  
See store item page for other formats.