


HM-2G Cut Sheet

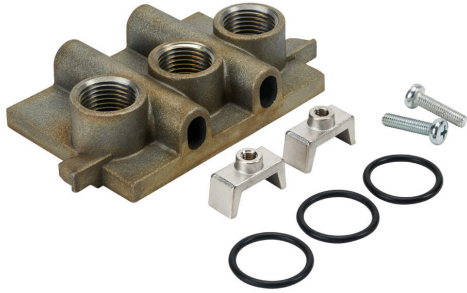

NITRA air manifold inlet, aluminum alloy, 145 psi (10 bar) maximum operating pressure, G1/2 female BSPP inlet(s), G1/2 female BSPP exhaust(s). For use with ISO 5599/1 size 2 manifolds.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HM-2G>

Technical Specifications

Brand	NITRA
Item	Air Manifold inlet
Material	Aluminum alloy
Maximum Operating Pressure	145 psi (10 bar)
Inlet Port	G1/2 female BSPP
Exhaust Port	G1/2 female BSPP
For Use With	ISO 5599/1 size 2 manifolds
Includes	Assembly clamps and seals

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document