


HMC-18B30-11-AS Cut Sheet

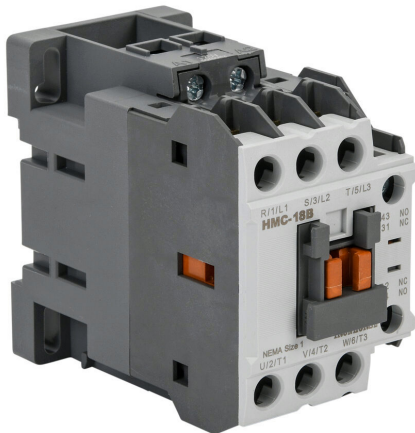

IronHorse IEC contactor, 18A, (3) N.O. power poles, (1) N.O./ (1) N.C. auxiliary contacts, 120 VAC (50/60Hz) coil voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HMC-18B30-11-AS>

Technical Specifications

Brand	IronHorse
Item	Contactor
Contactor Type	IEC
Actuator Type	Magnetic
Amperage Rating	18A
Power Poles	(3) N.O.
Auxiliary Contacts	(1) N.O./ (1) N.C.
Coil Voltage	120 VAC (50/60Hz)
Horsepower Rating	10hp
SCCR Rating	5kA SCCR
Mounting	35mm DIN rail or panel

Agency Approvals

UL Listed File #	E191059
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/HMC-18B30-11-AS.pdf>
See store item page for other formats.