


# HMC-9B30-11-CS Cut Sheet

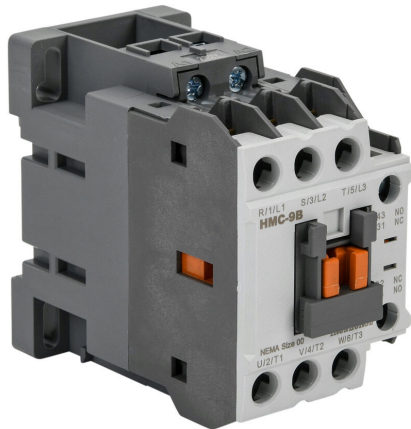

IronHorse IEC contactor, 9A, (3) N.O. power poles, (1) N.O./ (1) N.C. auxiliary contacts, 230 VAC (50/60Hz) coil voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HMC-9B30-11-CS>

## Technical Specifications

<b>Brand</b>	IronHorse
<b>Item</b>	Contactor
<b>Contactor Type</b>	IEC
<b>Actuator Type</b>	Magnetic
<b>Amperage Rating</b>	9A
<b>Power Poles</b>	(3) N.O.
<b>Auxiliary Contacts</b>	(1) N.O./ (1) N.C.
<b>Coil Voltage</b>	230 VAC (50/60Hz)
<b>Horsepower Rating</b>	5hp
<b>SCCR Rating</b>	5kA SCCR
<b>Mounting</b>	35mm DIN rail or panel

## Agency Approvals

<b>UL Listed File #</b>	E191059
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/HMC-9B30-11-CS.pdf>  
See store item page for other formats.