


# HN14C14-25YEL Cut Sheet

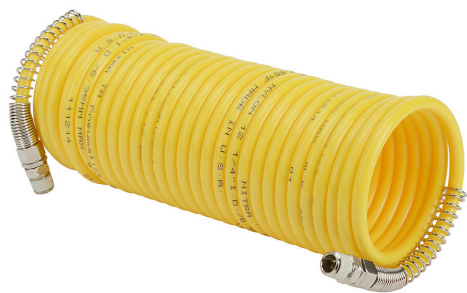

NITRA pneumatic coiled hose, nylon 12, yellow, 1/4in inside diameter, 0.3125in outside diameter, (2) 1/4in male NPT nickel-plated brass swivel fittings, 20ft working length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HN14C14-25YEL>

## Technical Specifications

Brand	NITRA
Item	Coiled hose
Working Fluid	Air or inert gas
Material	Nylon 12
Color	Yellow
Inside Diameter	1/4in
Outside Diameter	0.3125in
Connection	(2) 1/4in male NPT nickel-plated brass swivel fittings
Working Length	20ft working length
Operating Pressure	250 psi
Operating Temperature	-60 to +200 deg F

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/HN14C14-25YEL.pdf>  
See store item page for other formats.