


HN14C14-25YEL Cut Sheet

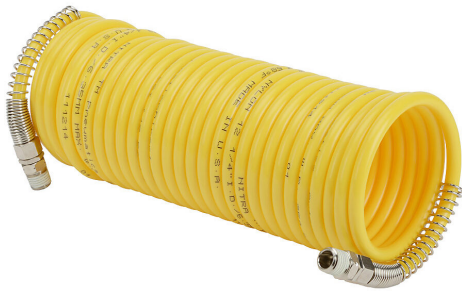

NITRA pneumatic coiled hose, nylon 12, yellow, 1/4in inside diameter, 0.3125in outside diameter, (2) 1/4in male NPT nickel-plated brass swivel fittings, 20ft working length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HN14C14-25YEL>

Technical Specifications

Brand	NITRA
Item	Pneumatic Coiled hose
Material	Nylon 12
Color	Yellow
Inside Diameter	1/4in
Outside Diameter	0.3125in
Connection	(2) 1/4in male NPT nickel-plated brass swivel fittings
Working Length	20ft working length
Operating Pressure	250 psi
Operating Temperature	-60 to +200 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document