


HP14C20CBL Cut Sheet

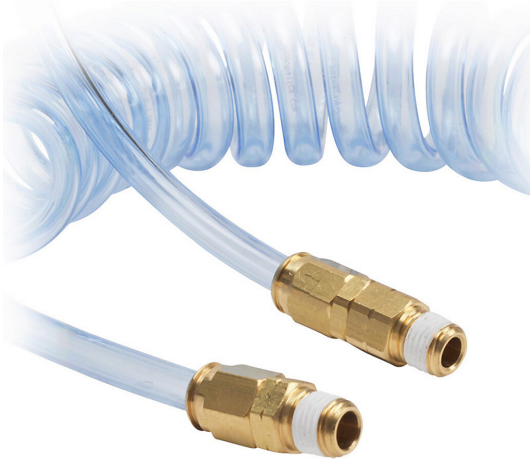

NITRA pneumatic coiled hose, polyurethane, clear blue, 1/4in inside diameter, 0.375in outside diameter, (2) 1/4in male NPT brass fittings (one end fixed, one end swivel), 16ft working length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HP14C20CBL>

Technical Specifications

Brand	NITRA
Item	Coiled hose
Working Fluid	Air or inert gas
Material	Polyurethane
Color	Clear blue
Inside Diameter	1/4in
Outside Diameter	0.375in
Connection	(2) 1/4in male NPT brass fittings (one end fixed, one end swivel)
Working Length	16ft working length
Operating Pressure	140 psi
Operating Temperature	-68 to +140 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document