


HPX1-AUX11-S Cut Sheet

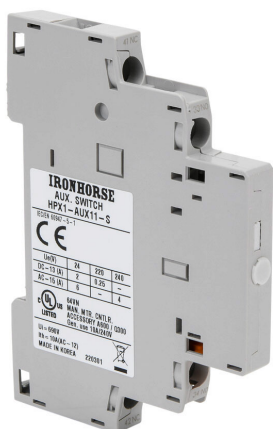

IronHorse field installable auxiliary contact, left side mount, (1) N.O./ (1) N.C. contact(s), 6A @ 120 VAC/0.55A @ 120 VDC, screw terminal. For use with HMMP-32H to HMMP-100H manual motor protectors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HPX1-AUX11-S>

Technical Specifications

| | |
|--------------------------|---|
| Brand | IronHorse |
| Item | Auxiliary contact |
| Field Installable | Yes |
| Mounting | Left side |
| Contact Type | (1) N.O./ (1) N.C. |
| Amperage Rating | 6A @ 120 VAC/0.55A @ 120 VDC |
| Connection | Screw terminal |
| For Use With | HMMP-32H to HMMP-100H manual motor protectors |

Agency Approvals

| | |
|-------------------------|--|
| UL Listed File # | E195426, E531281 |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/HPX1-AUX11-S.pdf>
See store item page for other formats.