


# HPX1-MALM11-S Cut Sheet

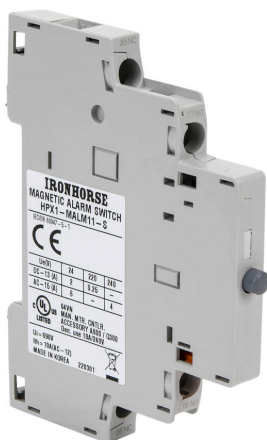

IronHorse field installable short circuit alarm contact, left side mount, (1) N.O./(1) N.C. contact(s), 6A @ 120 VAC/0.55A @ 120 VDC, screw terminal. For use with HMMP-32H to HMMP-100H manual motor protectors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HPX1-MALM11-S>

## Technical Specifications

Brand	IronHorse
Item	Short circuit alarm contact
Field Installable	Yes
Mounting	Left side
Contact Type	(1) N.O./(1) N.C.
Amperage Rating	6A @ 120 VAC/0.55A @ 120 VDC
Connection	Screw terminal
For Use With	HMMP-32H to HMMP-100H manual motor protectors
Additional Information	Indicates a short-circuit trip only

## Agency Approvals

UL Listed File #	E195426, E531281
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/HPX1-MALM11-S.pdf>  
See store item page for other formats.