


HS4GH02A24 Cut Sheet

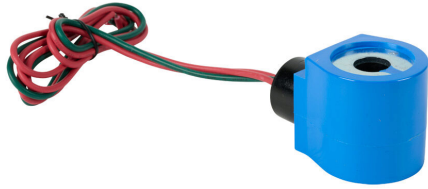

GC Valves solenoid coil, 120 VAC, 10W, 24in 18 AWG pigtail. For use with S201, NS201, S301 and NS301 valves.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HS4GH02A24>

Technical Specifications

Brand	GC Valves
Item	Solenoid coil
Replacement	No
Voltage Rating	120 VAC
Power Rating	10W
Electrical Connection	24in 18 AWG pigtail
For Use With	S201, NS201, S301 and NS301 valves

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document