


# HTOR32-0.16-S Cut Sheet

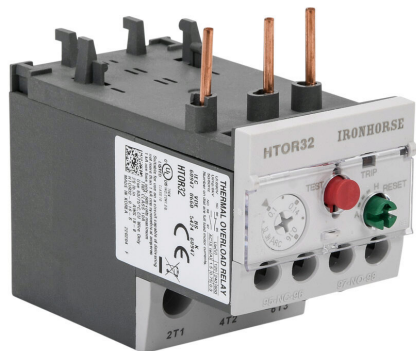

IronHorse thermal overload relay, 0.10-0.16A adjustable, bi-metallic, direct mount power connection(s). For use with HMC-9 to HMC-40 contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HTOR32-0.16-S>

## Technical Specifications

<b>Brand</b>	IronHorse
<b>Item</b>	Relay
<b>Relay Type</b>	Thermal overload
<b>Full Load Amperage Range</b>	0.10-0.16A adjustable
<b>Operation Type</b>	Bi-metallic
<b>Auxiliary Contacts</b>	(1) N.O. / (1) N.C.
<b>Trip Class</b>	Trip Class 10A
<b>Phase Loss Sensitive</b>	Yes
<b>Ground Fault Protection</b>	No
<b>Connection</b>	Direct mount power
<b>For Use With</b>	HMC-9 to HMC-40 contactors

## Agency Approvals

<b>UL Listed File #</b>	E191072
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/HTOR32-0.16-S.pdf>  
See store item page for other formats.