


HTOR32-0.40-S Cut Sheet

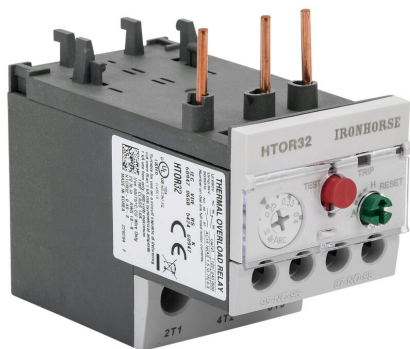

IronHorse thermal overload relay, 0.25-0.40A adjustable, bi-metallic, direct mount power connection(s). For use with HMC-9 to HMC-40 contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HTOR32-0.40-S>

Technical Specifications

Brand	IronHorse
Item	Relay
Relay Type	Thermal overload
Full Load Amperage Range	0.25-0.40A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O./ (1) N.C.
Trip Class	Trip Class 10A
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	HMC-9 to HMC-40 contactors

Agency Approvals

UL Listed File #	E191072
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/HTOR32-0.40-S.pdf>
See store item page for other formats.