


HTOR32-25-S Cut Sheet

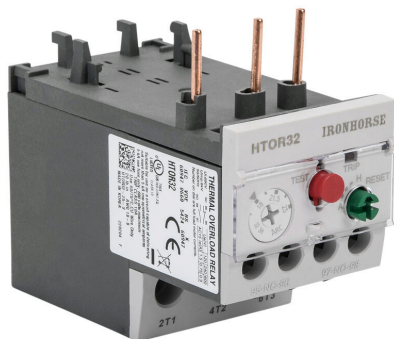

IronHorse thermal overload relay, 18-25A adjustable, bi-metallic, direct mount power connection(s). For use with HMC-9 to HMC-40 contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/HTOR32-25-S>

Technical Specifications

| | |
|---------------------------------|----------------------------|
| Brand | IronHorse |
| Item | Relay |
| Relay Type | Thermal overload |
| Full Load Amperage Range | 18-25A adjustable |
| Operation Type | Bi-metallic |
| Auxiliary Contacts | (1) N.O./ (1) N.C. |
| Trip Class | Trip Class 10A |
| Phase Loss Sensitive | Yes |
| Ground Fault Protection | No |
| Connection | Direct mount power |
| For Use With | HMC-9 to HMC-40 contactors |

Agency Approvals

| | |
|-------------------------|--|
| UL Listed File # | E191072 |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/HTOR32-25-S.pdf>
See store item page for other formats.