


# J10MD-MA Cut Sheet

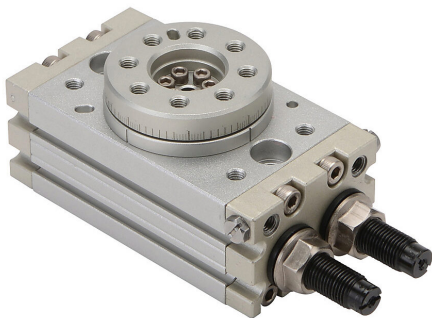

NITRA pneumatic rotary actuator, double acting, size 10, 0 to 190 degrees, shock absorbers, anodized aluminum body, M5 x 0.8 female ISO port(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/J10MD-MA>

## Technical Specifications

Brand	NITRA
Item	Rotary actuator
Working Fluid	Air or inert gas
Action Type	Double acting
Size	10
Adjustable Travel	0 to 190 degrees
Cushion Type	Shock absorbers
Body Material	Anodized aluminum
Port Size	M5 x 0.8 female ISO

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/J10MD-MA.pdf>  
See store item page for other formats.