


# J20MD-MA Cut Sheet

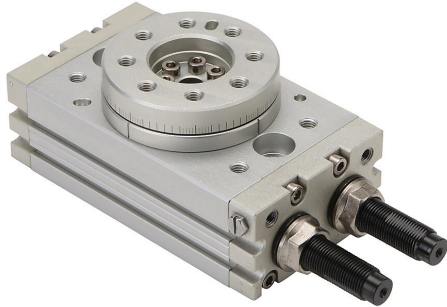

NITRA pneumatic rotary actuator, double acting, size 20, 0 to 190 degrees, shock absorbers, anodized aluminum body, M5 x 0.8 threaded port(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/J20MD-MA>

---

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Rotary actuator
<b>Working Fluid</b>	Pneumatic
<b>Action Type</b>	Double acting
<b>Size</b>	20
<b>Adjustable Travel</b>	0 to 190 degrees
<b>Cushion Type</b>	Shock absorbers
<b>Body Material</b>	Anodized aluminum
<b>Port Information</b>	M5 x 0.8 threaded

---

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>