


JM60400-1MW16-1 Cut Sheet

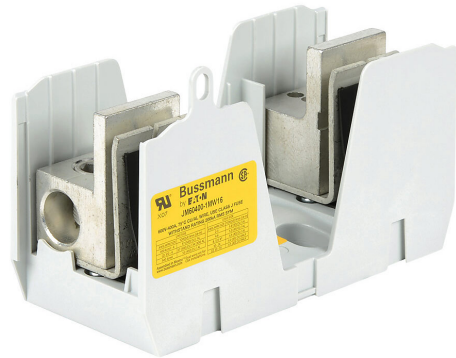

Bussmann modular power distribution fuse block, multi-wire, accepts J fuses, 400A, 600V, 1-pole, 1 line/6 load opening(s) per pole, box lug, panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/JM60400-1MW16-1>

Technical Specifications

Brand	Bussmann
Item	Power distribution fuse block
Modular	Yes
Blown Fuse Indicator	No
Multi-Wire	Yes
Accepts Fuse Class	J
Amperage Rating	400A
Voltage Rating	600V
Number of Poles	1
Openings Per Pole	1 line/6 load
Line Side Conductor Size	4 AWG-600 MCM copper or aluminum
Load Side Conductor Size	(6) 14-2 AWG copper or (6) 8-2 AWG aluminum
Conductor Connection Type	Box lug
SCCR Rating	200kA SCCR
Fuse Connection Type	Clip with reinforced spring
Mounting	Panel
Additional Information	Covers sold separately

Agency Approvals

UL Listed File #	None
UL Recognized File #	E14853
UL Hazardous File #	None
CE	View CE declarations
CSA File #	47235 - 6225-01
RoHS Status	No
EU REACH	View EU REACH document
Other	None